

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301230147](#)
Status: **Active**
Description: I-Beam Festoon Intermediate Car Round S6 Steel Wheels and Kick-up Wheels

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Festoons
Series	130123
Cable Height - Maximum	26.16mm (1.030")
Combined Cable Weight-Max./Car	158.76kg (350.0 lb)
Component Type	Car - Intermediate
Depth	209.55mm (8.250")
Duty	Heavy
Height	336.55mm (13.250")
Length	325.88mm (12.830")
Product Name	Aero-Motive
Type	I-Beam
UPC	78678862933

Physical


Beam Size	S6 - 152.40mm
Material - Coating	Powder Coating
Material - Metal	Steel
Material - Wheel	Steel
Net Weight	999.990/kg
Number of Cars	1
Packaging Type	Individual Carton
Saddle Radius	112.78mm (4.440")
Thread Size	N/A
Travel Speed - Maximum	121.92 mpm (400 fpm)
Wire/Cable Type	Round

Electrical

Voltage - Maximum	600V
-------------------	------

Material Info

Engineering Number	S639611
--------------------	---------

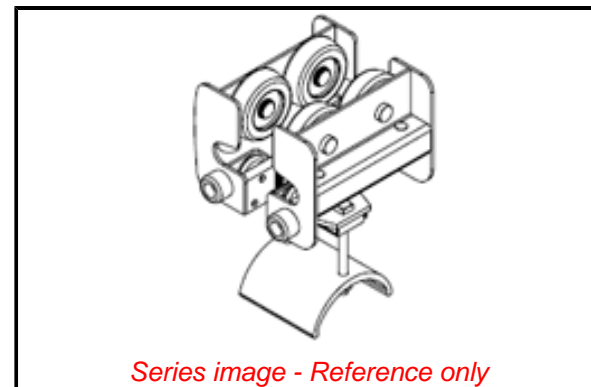

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130123 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301230147](#)