


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301280120](#)

Status: **Active**

Overview: [Outlet Boxes](#)

Description: Woodhead FD Yellow Glass-Filled Polyester Box, Corrosion -resistant, (2) 25.40mm (1.000") Threaded Knock-out Openings, GFCI 20A/125V, with Watertite Silicone Coverplate

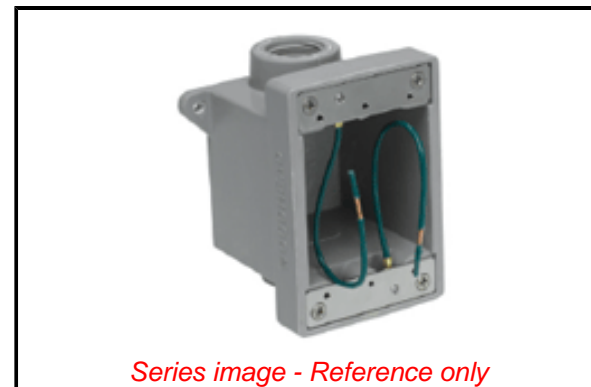

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Power Distribution
Series	130128
Enclosure Rating	N/A
GFCI Reset	N/A
Mounting Style	Permanent
Open Neutral Relay	N/A
Overview	Outlet Boxes
Product Name	Woodhead
Receptacle Type	N/A
Type	FD Box - Industrial Duty
UPC	78678815162

Physical

Cord Diameter	N/A
Cord Grip Body Size	N/A
Cord Length	N/A
Feed-Thru	No
Flip Lid	No
Material - Housing	PBT Glass-Filled
Number of Receptacles	0
Packaging Type	Carton

Electrical

Cord Type	N/A
Current - Maximum per Contact	N/A
GFCI	No
Ground Continuity Monitor	No
NEMA Configuration	N/A
Voltage - Maximum	N/A

Material Info

Engineering Number	454GF
--------------------	-------

Reference - Drawing Numbers

Sales Drawing	1301280117-000
---------------	----------------

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130128 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130128-0120](#)