

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301350219](#)
Status: **Active**
Overview: [Outlet Boxes](#)
Description: Super-Safeway GFCI Multiple Outlet Box with Ground Continuity Monitor, Open Neutral Relay, (2) NEMA 5-20 Duplex with Flip Lids, 0.305m (1.0') Cord Length, 12/3 SOOW Cord, NEMA 5-20 Plug

Documents:

[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|--------------------|------------------------------|
| Product Family | Power Distribution |
| Series | 130135 |
| Enclosure Rating | NEMA 4 |
| GFCI Reset | Manual |
| Mounting Style | Portable |
| Open Neutral Relay | Yes |
| Overview | Outlet Boxes |
| Product Name | Super-Safeway |
| Receptacle Type | Duplex |
| Type | GFCI Multiple Outlet Box |
| UPC | 78678876132 |

Physical


| | |
|-----------------------|-----------------|
| Cord Diameter | 15.24mm (.600") |
| Cord Grip Body Size | F3 3/4" |
| Cord Length | 0.305m (1.0') |
| Feed-Thru | No |
| Flip Lid | Yes |
| Material - Housing | Rubber |
| Number of Receptacles | 2 |
| Packaging Type | Carton |

Electrical

| | |
|-------------------------------|-----------|
| Cord Type | 12/3 SOOW |
| Current - Maximum per Contact | 20.0A |
| GFCI | Yes |
| Ground Continuity Monitor | Yes |
| NEMA Configuration | NEMA 5-20 |
| Voltage - Maximum | N/A |

Material Info

| | |
|--------------------|------------|
| Engineering Number | 32GM20E123 |
|--------------------|------------|

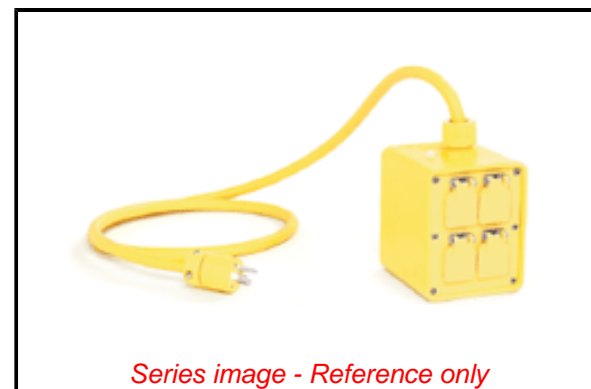

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130135 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301350219](#)