

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301350257](#)

**Status:** **Active**

**Overview:** [Outlet Boxes](#)

**Description:** Super-Safeway Angled GFCI Outlet Box, F3 (3/4") Cord Grip Body, Including NEMA 5-20 GFCI & Duplex Receptacles with Flip Lids and 7.62m (25.0') Cord Length, 12/3 SOOW Cord

**Documents:**

[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Power Distribution
Series	<a href="#">130135</a>
Enclosure Rating	NEMA 4
GFCI Reset	Manual
Mounting Style	Portable
Open Neutral Relay	No
Overview	<a href="#">Outlet Boxes</a>
Product Name	Super-Safeway
Receptacle Type	GFCI Duplex
Type	Angled GFCI Outlet Box
UPC	78678809512

**Physical**


Cord Diameter	15.24mm (.600")
Cord Grip Body Size	F3 3/4"
Cord Length	7.62m (25.0')
Feed-Thru	No
Flip Lid	Yes
Material - Housing	Rubber
Number of Receptacles	2
Packaging Type	Carton

**Electrical**

Cord Type	12/3 SOOW
Current - Maximum per Contact	20.0A
GFCI	Yes
Ground Continuity Monitor	No
NEMA Configuration	NEMA 5-20
Voltage - Maximum	120V

**Material Info**

Engineering Number	3322A123
--------------------	----------

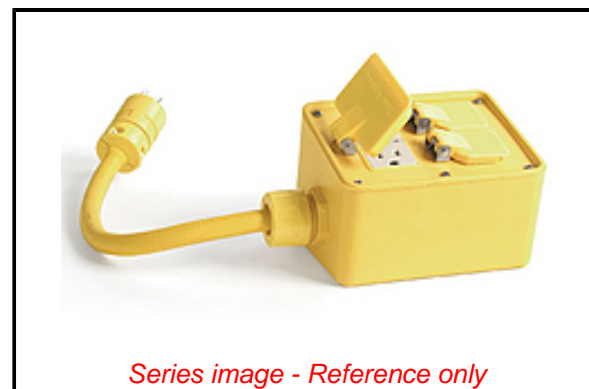

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130135 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301350257](#)