

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301370224](#)  
**Status:** **Active**  
**Overview:** [Watertite Extreme Wet-Location Wiring Solutions](#)  
**Description:** Watertite GFCI Multiple Outlet FD Box, (1) NEMA 5-15 Duplex with Flip Lids, 1.83m (6.0') Cord Length, 14/3 SOOW Cord, NEMA 5-15 Watertite Plug

**Documents:**

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Power Distribution
Series	<a href="#">130137</a>
Enclosure Rating	NEMA 4X
GFCI Reset	Manual
Mounting Style	Portable
Open Neutral Relay	No
Overview	<a href="#">Watertite Extreme Wet-Location Wiring Solutions</a>
Product Name	Watertite
Receptacle Type	Duplex
Type	GFCI Multiple Outlet Box
UPC	78678809451

**Physical**


Cord Diameter	13.59mm (.535")
Cord Grip Body Size	F3 3/4"
Cord Length	1.83m (6.0')
Feed-Thru	No
Flip Lid	Yes
Material - Housing	Nylon
Net Weight	2140.954/g
Number of Receptacles	1
Packaging Type	Carton

**Electrical**

Cord Type	14/3 SOOW
Current - Maximum per Contact	15.0A
GFCI	Yes
Ground Continuity Monitor	No
NEMA Configuration	NEMA 5-15
Voltage - Maximum	120V

**Material Info**

Engineering Number	3301GFL143
--------------------	------------

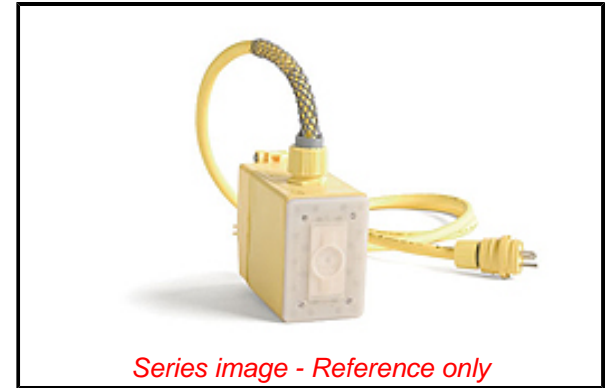

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130137 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301370224](#)