

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301380083](#)
Status: **Active**
Overview: Watertite Extreme Wet-Location Wiring Solutions
Description: Watertite Multiple Outlet Pendant Box, GFCI, (1) NEMA 5-15 Duplex with Flip Lids, 7.62m (25.0') Cord Length, 12/3 SOOW Cord, Double Eye Wire Mesh Support Grip

Documents:

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Power Distribution
Series	130138
Enclosure Rating	NEMA 4
GFCI Reset	Manual
Mounting Style	Portable
Open Neutral Relay	No
Overview	<u>Watertite Extreme Wet-Location Wiring Solutions</u>
Product Name	Watertite
Receptacle Type	Duplex
Type	Multiple Outlet Box
UPC	78678823265

Physical


Cord Diameter	13.59mm (.535")
Cord Grip Body Size	F3 3/4"
Cord Length	7.62m (25.0')
Feed-Thru	No
Flip Lid	Yes
Material - Housing	Rubber
Net Weight	55.110/g
Number of Receptacles	1
Packaging Type	Carton

Electrical

Cord Type	14/3 SOOW
Current - Maximum per Contact	15.0A
GFCI	Yes
Ground Continuity Monitor	No
NEMA Configuration	NEMA 5-20
Voltage - Maximum	N/A

Material Info

Engineering Number	70W47A143GF
--------------------	-------------

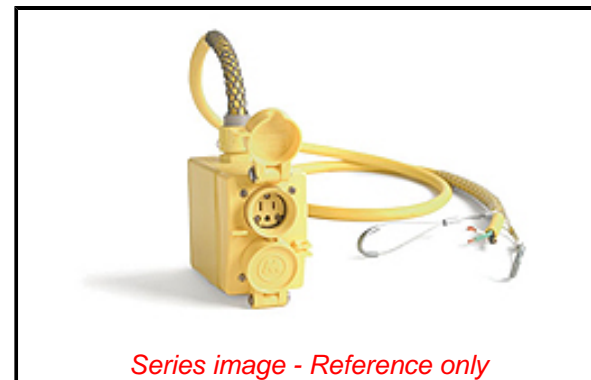

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130138](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301380083](#)