

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301380095](#)

Status: **Active**

Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)

Description: Watertite Outlet Pendant Box, GFCI, (1) NEMA L5-20 Single Receptacle with Flip Lid, 4.57m (15.0') Cord Length, 12/3 SOOW Cord, Double Eye Wire Mesh Cord Grip

Documents:

[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Power Distribution
Series	130138
Enclosure Rating	NEMA 4
GFCI Reset	Manual
Mounting Style	Portable
Open Neutral Relay	No
Overview	Watertite Extreme Wet-Location Wiring Solutions
Product Name	Watertite
Receptacle Type	Single
Type	Single Outlet Box
UPC	78678810126

Physical


Cord Diameter	15.24mm (.600")
Cord Grip Body Size	F3 3/4"
Cord Length	4.57m (15.0')
Feed-Thru	No
Flip Lid	Yes
Material - Housing	Rubber
Net Weight	412.000/g
Number of Receptacles	1
Packaging Type	Carton

Electrical

Cord Type	12/3 SOOW
Current - Maximum per Contact	20.0A
GFCI	Yes
Ground Continuity Monitor	No
NEMA Configuration	NEMA L5-20
Voltage - Maximum	125V

Material Info

Engineering Number	77W47M123GF
--------------------	-------------

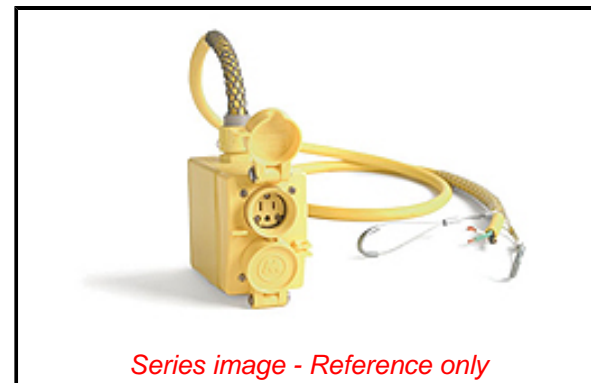

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130138](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301380095](#)