

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460023](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: Watertite Extreme Plug, 2 Pole/3 Wire, NEMA 5-20, 125V, Cord Grip Body Size F2, Black, Silicone Husk

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E10176

General

Product Family Wiring Devices
 Series [130146](#)
 IP Rating IP69K
 NEMA Configuration NEMA 5-20
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)
 Product Name Watertite Extreme
 Receptacle Type N/A
 Specialty N/A
 Type Plug
 UPC 78678871046

Physical

Cord Grip Body Size F2 1/2"
 Flange No
 Flip Lid No
 Gender Male
 Length N/A
 Locking Blade No
 Net Weight 125.000/kg
 Poles 2-pole/3-wire

Electrical


Cord Type N/A
 Current - Maximum per Contact 20.0A
 GFCI No
 Lighted Connector No
 Voltage - Maximum 125V

Material Info

Engineering Number 14W33BLK

Reference - Drawing Numbers

Sales Drawing 1301460022-000

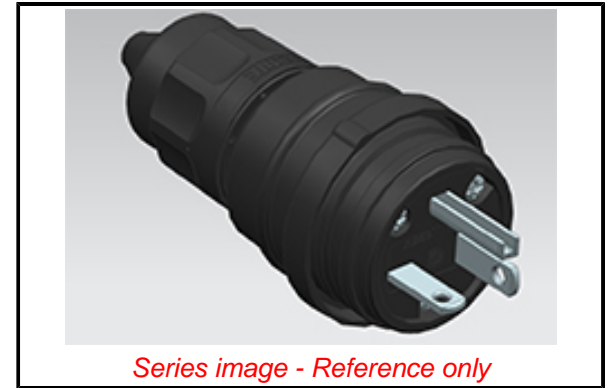

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130146 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301460023](#)