

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460078](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: [Watertite Extreme Plug with Locking Blade, 3 Pole/3 Wire, Non-NEMA, 15A/125V, 10A/250V, Cord Grip Body Size F2, Silicone Husk](#)

Documents:

[Datasheet \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family [Wiring Devices](#)
 Series [130146](#)
 IP Rating [IP69K](#)
 NEMA Configuration [Non-NEMA](#)
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)
 Product Name [Watertite Extreme](#)
 Receptacle Type [N/A](#)
 Specialty [N/A](#)
 Type [Plug](#)
 UPC [78678871280](#)

Physical


Cord Grip Body Size [F2 1/2"](#)
 Flange [No](#)
 Flip Lid [No](#)
 Gender [Male](#)
 Length [N/A](#)
 Locking Blade [Yes](#)
 Net Weight [128.366/g](#)
 Poles [3-pole/3-wire](#)

Electrical

Cord Type [N/A](#)
 Current - Maximum per Contact [15.0A](#)
 GFCI [No](#)
 Lighted Connector [No](#)
 Voltage - Maximum [250V](#)

Material Info

Engineering Number [24W07](#)

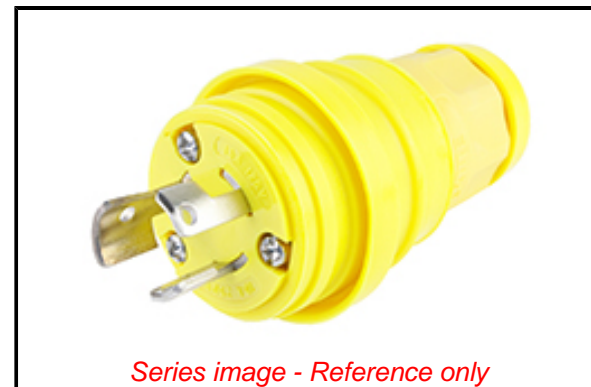

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130146 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1301460078](#) [24W07](#)