

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460094](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: Watertite Extreme Connector for Male Receptacle with Locking Blade, 3 Pole/3 Wire, Non-NEMA 15A/125V, 10A/250V, F2, Silicone Husk

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Wiring Devices
Series	130146
IP Rating	IP69K
NEMA Configuration	Non-NEMA Locking
Overview	Watertite Extreme Wet-Location Wiring Solutions
Product Name	Watertite Extreme
Receptacle Type	Single
Specialty	N/A
Type	Connector
UPC	78678871184

Physical

Cord Grip Body Size	F2 1/2"
Flange	No
Flip Lid	No
Gender	Female
Length	N/A
Locking Blade	Yes
Poles	3-pole/3-wire

Electrical


Cord Type	N/A
Current - Maximum per Contact	10.0A, 15.0A
GFCI	No
Lighted Connector	No
Voltage - Maximum	125V / 250V

Material Info

Engineering Number	25W07MB
--------------------	---------

Reference - Drawing Numbers

Sales Drawing	1301460094-000
---------------	----------------

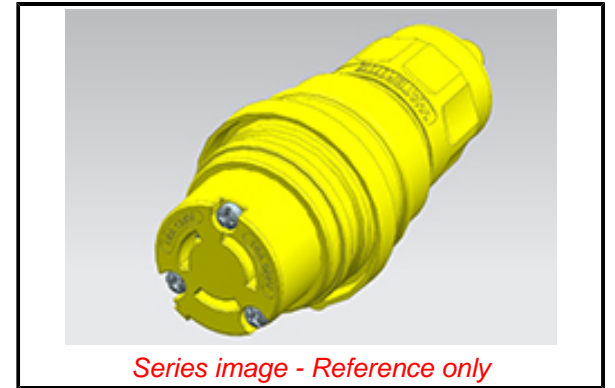

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[130146 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301460094](#)