

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301470018](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: Watertite Extreme Plug with Locking Blade, 2 Pole/3 Wire, NEMA L5-20, 125V, Cord Grip Body Size F3

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E10176

General

Product Family Wiring Devices
 Series [130147](#)
 IP Rating IP67
 NEMA Configuration NEMA L5-20
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)
 Product Name Watertite Extreme
 Receptacle Type N/A
 Specialty N/A
 Type Plug
 UPC 78678871211

Physical

Cord Grip Body Size F3 3/4"
 Flange No
 Flip Lid No
 Gender Male
 Length N/A
 Locking Blade Yes
 Net Weight 222.260/g
 Poles 2-pole/3-wire

Electrical


Cord Type N/A
 Current - Maximum per Contact 20.0A
 GFCI No
 Lighted Connector No
 Voltage - Maximum 125V

Material Info

Engineering Number 26W47

Reference - Drawing Numbers

Sales Drawing 1301470018-000

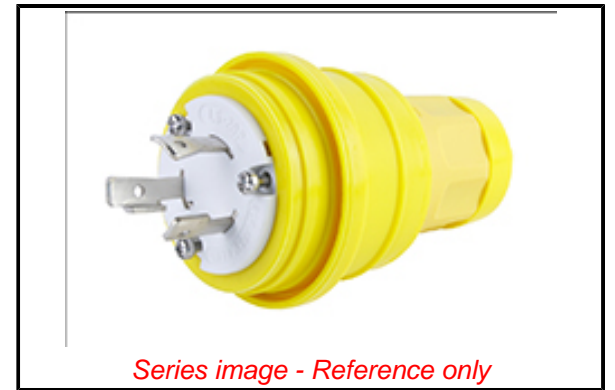

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130147 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1301470018](#) [26W47](#)