

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301470077](#)  
**Status:** **Active**  
**Overview:** [Watertite Extreme Wet-Location Wiring Solutions](#)  
**Description:** Watertite Extreme Plug with Locking Blade, 3 Pole/4 Wire, NEMA L14-30, 125V/250V, Cord Grip Body Size F4

**Documents:**

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E10176

**General**

Product Family Wiring Devices  
 Series [130147](#)  
 Comments 125V and 250V  
 IP Rating IP67  
 NEMA Configuration NEMA L14-30  
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)  
 Product Name Watertite Extreme  
 Receptacle Type N/A  
 Specialty N/A  
 Type Plug  
 UPC 78678871235

**Physical**


Cord Grip Body Size F4 1"  
 Flange No  
 Flip Lid No  
 Gender Male  
 Length N/A  
 Locking Blade Yes  
 Net Weight 295.500/g  
 Poles 3-pole/4-wire

**Electrical**

Cord Type N/A  
 Current - Maximum per Contact 30.0A  
 GFCI No  
 Lighted Connector No  
 Voltage - Maximum 125V / 250V

**Material Info**

Engineering Number 28W74

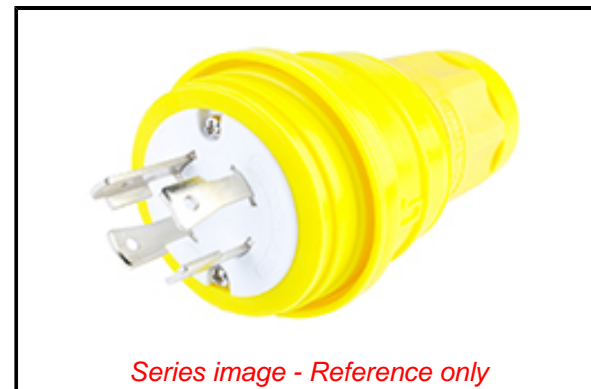

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130147 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1301470077](#) [28W74](#)