

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301470086](#)  
**Status:** **Active**  
**Overview:** [Watertite Extreme Wet-Location Wiring Solutions](#)  
**Description:** [Watertite Extreme Plug with Locking Blade, 4 Pole/5 Wire, NEMA L22-30, 3ø 480V, Cord Grip Body Size F4](#)

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Brochure \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E10176

**General**

Product Family [Wiring Devices](#)  
 Series [130147](#)  
 IP Rating [IP67](#)  
 NEMA Configuration [NEMA L22-30](#)  
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)  
 Product Name [Watertite Extreme](#)  
 Receptacle Type [N/A](#)  
 Specialty [N/A](#)  
 Type [Plug](#)  
 UPC [78678871115](#)

**Physical**

Cord Grip Body Size [F4 1"](#)  
 Flange [No](#)  
 Flip Lid [No](#)  
 Gender [Male](#)  
 Length [N/A](#)  
 Locking Blade [Yes](#)  
 Poles [4-pole/5-wire](#)

**Electrical**


Cord Type [N/A](#)  
 Current - Maximum per Contact [30.0A](#)  
 GFCI [No](#)  
 Lighted Connector [No](#)  
 Voltage - Maximum [3ø 480V](#)

**Material Info**

Engineering Number [28W82](#)

**Reference - Drawing Numbers**

Sales Drawing [1301470086-000](#)

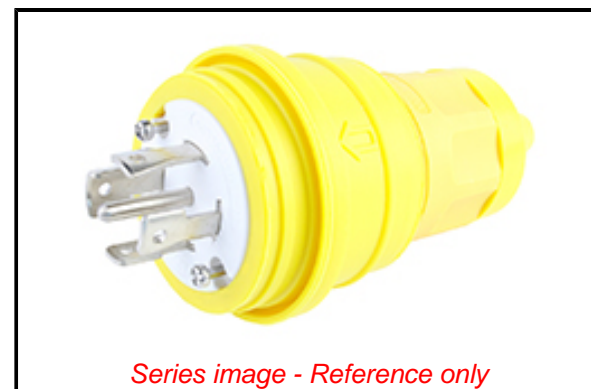

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130147 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1301470086](#) [28W82](#)