

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1302990300](#)  
**Status:** **Active**  
**Overview:** Brad Micro-Change (M12) Connectors  
**Description:** Brad Micro-Change (M12) Harsh-Duty Receptacle, 5 Pole, A-Code, Right-Angle

**Documents:**

[Drawing \(PDF\)](#) [Packaging Specification PK-130299-001-001 \(PDF\)](#)  
[Product Specification PS-130299-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family Industrial Receptacles  
 Series [130299](#)  
 IP Rating IP67  
 Overview [Brad Micro-Change \(M12\) Connectors](#)  
 Product Name Micro-Change (M12)  
 Type PCB Mount  
 UPC 78172513054

**Physical**

Coupling Type Internal Thread  
 Gender Female  
 Keyway A-coded  
 Length N/A  
 Material - Component Nickel-plated Zinc Die-Cast  
 Mounting Thread Size M12 x 1.0  
 Net Weight 321.000/g  
 Orientation 90° Angle  
 Panel Mount Back, Front  
 Poles 5  
 Temperature Range - Operating -40° to +85°C  
 Wire Size AWG N/A  
 Wire/Cable Type N/A


**Electrical**

Current - Maximum per Contact 4.0A  
 Voltage - Maximum 250V AC/DC

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification PK-130299-001-001  
 Product Specification PS-130299-001-001  
 Sales Drawing SD-130299-007-001

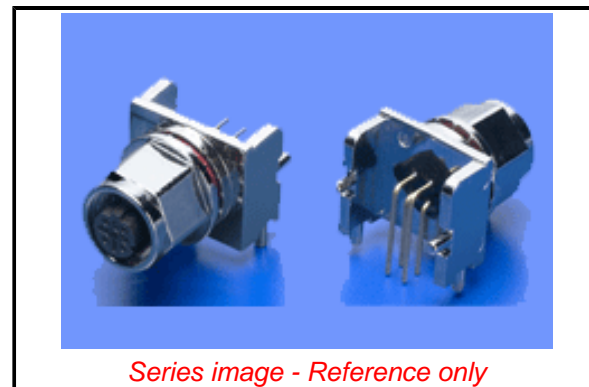

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - D(2020)9139-DC (19 Jan 2021)  
 Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]o Lead

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Reviewed

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[130299 Series](#)

**Mates With**

Male A-Code Cable Assembly

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[130299-0300](#)