


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1510340014](#)
Status: **Active**
Overview: EXTreme Guardian System
Description: 11.00mm Pitch EXTreme Guardian Power Receptacle Assembly, 6 AWG, PBT, 4 Circuits

Documents:

3D Model	Product Specification PS-151053-0000-001 (PDF)
Drawing (PDF)	Packaging Specification PK-151034-0001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

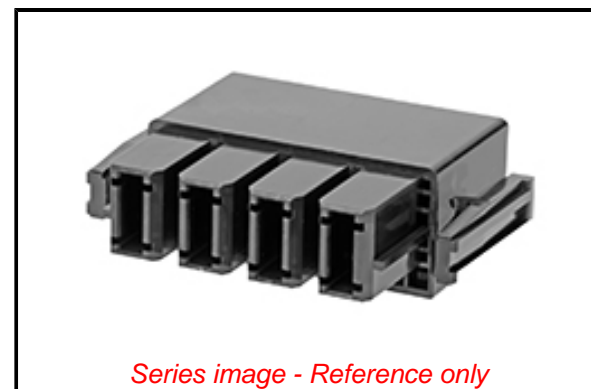

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	151034
Application	Power, Wire-to-Board
Overview	EXTreme Guardian System
Product Name	EXTreme Guardian
UPC	889056225182

Physical

Circuits (maximum)	4
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	22.141/g
Number of Rows	1
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	11.00mm
Temperature Range - Operating	-40° to +105°C

Electrical

Current - Maximum per Contact	80.0A
-------------------------------	-------

Solder Process Data

Lead-free Process Capability	N/A
------------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-151034-0001-001
Product Specification	PS-151053-0000-001
Sales Drawing	SD-151034-0001-001

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Pyrene
Fluoranthene
Tris(4-nonylphenyl,
branched and linear)
phosphi
Boric acid
diisohexyl phthalate
Terphenyl,
hydrogenated
1,3-Propanesultone
Dibutyltin-dichloride
Benzo(ghi)perylene
Phenanthrene
Dicyclohexyl-
phthalate
Silicic acid (H₂Si₂O₅),
barium salt (1:1),
lead-
Sulfurous Acid, Lead
Salt, Dibasic
Cadmium Hydroxide
Cyanamide, lead(2+)
salt (1:1)
Lead titanium
zirconium oxide
Dioxobis(stearato)trilead
Tetralead-trioxide-
sulphate
Trilead-dioxide-
phosphonate
Pentalead-tetraoxide-
sulphate
Lead-dinitrate
pyrochlore, antimony
lead yellow
Diboron-trioxide

China RoHS

Diarsenic-trioxide
Halogen-Free
Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

[151034](#) Series

Mates With

[151035](#) EXTreme Guardian Power Right-Angle PCB Header, [151053](#) EXTreme Guardian Power Vertical PCB Header

Use With

[46818](#) Power Harness Crimp Receptacle, [151076](#) TPA Clips, [46819](#) High-Power Terminals

This document was generated on 09/02/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[151034-0014](#)