

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1552200103](#)
Status: **Active**
Overview: [Flamar Standard and Custom Cables for Industrial Automation](#)
Description: Flamar Control Cable, WSOR Jacket, Unshielded, 2 Circuits, 0.50mm² / 21 AWG, 5.20mm (.205") Diameter, 600.0m (1968.50') Length, Gray

Documents:

[Product Specification 1552200001-P1E \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

General

| | |
|-------------------------|---|
| Product Family | Cable |
| Series | 155220 |
| Comments | 3 reels of 200.0m each |
| Crimp Quality Equipment | Yes |
| Geographic Area | Global |
| Overview | Flamar Standard and Custom Cables for Industrial Automation |
| Product Name | Flamar, Signal and Control |
| UPC | 889056458672 |

Physical

| | |
|-------------------------------|--------------------|
| Bending Radius - Minimum | > 7.5xOD |
| Cable Length | 600.0m |
| Circuits (Loaded) | 2 |
| Color - Cable Jacket | Gray |
| Insulation | TPE |
| Material - Outer Jacket | WSOR |
| Net Weight | 0.010/g |
| Outer Jacket Diameter | 5.20mm |
| Packaging Type | Reel |
| Temperature Range - Operating | -25° to +80°C |
| Wire Size AWG | 21 |
| Wire Size mm ² | 0.50 |
| Wire/Cable Type | UL AWM 21215 / CSA |

Electrical


| | |
|-------------------------------|---------------|
| Current - Maximum per Contact | Contact Molex |
| Voltage - Maximum | 600V |

Material Info

| | |
|--------------------|--------|
| Engineering Number | 3X200M |
|--------------------|--------|

Reference - Drawing Numbers

| | |
|-----------------------|----------------|
| Product Specification | 1552200001-P1E |
|-----------------------|----------------|

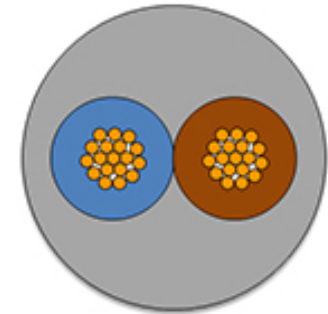

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[155220](#) Series

Use With

DIN Valve Connectors [121201](#) , [121202](#) , [121207](#) , [121208](#) , [121205](#) , [121211](#)

Micro-Change (M12) [120071](#)
Ultra-Lock (M12) [120085](#)
GWconnect Heavy Duty Connectors [93601](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155220-0103](#)