

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1552300233](#)

Status: **Active**

Overview: Flamar Standard and Custom Cables for Industrial Automation

Description: Flamar Control Cable, PUR Jacket, Unshielded, 4 Circuits, 1.50mm² with Green-Yellow Ground / 16 AWG with Green-Yellow Ground, 7.90mm (.311") Diameter, 500.0m (1640.42') Length, Gray

Documents:

[Product Specification 1552300001-P1E \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Brochure \(PDF\)](#)

General

| | |
|-------------------------|---|
| Product Family | Cable |
| Series | 155230 |
| Crimp Quality Equipment | Yes |
| Geographic Area | Global |
| Overview | Flamar Standard and Custom Cables for Industrial Automation |
| Product Name | Flamar, Signal and Control |
| UPC | 889056448963 |

Physical

| | |
|-------------------------------|--------------------|
| Bending Radius - Minimum | > 7.5xOD |
| Cable Length | 500.0m |
| Circuits (Loaded) | 4 |
| Color - Cable Jacket | Gray |
| Insulation | TPE |
| Material - Outer Jacket | PUR |
| Net Weight | 0.010/g |
| Outer Jacket Diameter | 7.90mm |
| Packaging Type | Reel |
| Temperature Range - Operating | -40° to +80°C |
| Wire Size AWG | 16 |
| Wire Size mm ² | 1.50 |
| Wire/Cable Type | UL AWM 21223 / CSA |

Electrical


| | |
|-------------------------------|---------------|
| Current - Maximum per Contact | Contact Molex |
| Voltage - Maximum | 1000V |

Material Info

| | |
|--------------------|--------|
| Engineering Number | 1X500M |
|--------------------|--------|

Reference - Drawing Numbers

| | |
|-----------------------|----------------|
| Product Specification | 1552300001-P1E |
|-----------------------|----------------|

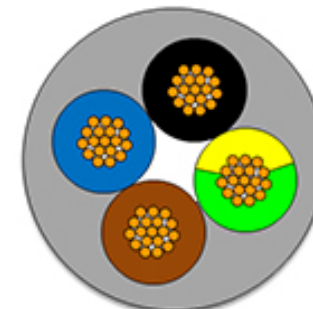

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

| | |
|-----------------|--------------|
| China ROHS | Not Reviewed |
| ELV | Not Reviewed |
| RoHS Phthalates | Not Reviewed |

Search Parts in this Series

[155230 Series](#)

Use With

DIN Valve Connectors [121201](#) , [121202](#) , [121207](#) , [121208](#) , [121205](#) , [121211](#)

Micro-Change (M12) [120071](#)
Ultra-Lock (M12) [120085](#)
GWconnect Heavy Duty Connectors [93601](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155230-0233](#)