

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1553210006](#)
Status: **Active**
Overview: Flamar Standard and Custom Cables for Industrial Automation
Description: Flamar Power Cable, WSOR Jacket, Braided Shielding Overall, 4 Circuits, 2.50mm² with Green-Yellow Ground / 14 AWG with Green-Yellow Ground, 10.60mm (.417") Diameter, 1000.0m (3280.83') Length, Orange

Documents:

[Product Specification 1553210001-P1E \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E172949

General

Product Family Cable
 Series [155321](#)
 Crimp Quality Equipment Yes
 Geographic Area Global
 Overview [Flamar Standard and Custom Cables for Industrial Automation](#)
 Product Name Flamar, Servo Motor
 UPC 889056460385

Physical

Bending Radius - Minimum > 10xOD
 Cable Length 1000.0m
 Circuits (Loaded) 4
 Color - Cable Jacket Orange
 Insulation TPE
 Material - Outer Jacket WSOR
 Net Weight 0.194/kg
 Outer Jacket Diameter 10.60mm
 Packaging Type Wooden Drum
 Temperature Range - Operating -25° to +80°C
 Wire Size AWG 14
 Wire Size mm² 2.50
 Wire/Cable Type UL AWM 21939 / CSA

Electrical


Current - Maximum per Contact Contact Molex
 Voltage - Maximum 1000V

Material Info

Engineering Number 1X1000M

Reference - Drawing Numbers

Product Specification 1553210001-P1E

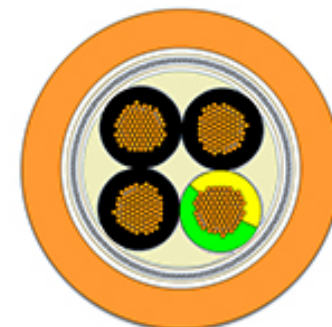

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2020)9139-DC (19
 Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[155321](#) Series

Use With

Brad M23 [120230](#) , [120233](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155321-0006](#)