

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1553210007](#)

Status: **Active**

Overview: [Flamar Standard and Custom Cables for Industrial Automation](#)

Description: Flamar Power Cable, WSOR Jacket, Braided Shielding Overall, 4 Circuits, 4.00mm² with Green-Yellow Ground / 12 AWG with Green-Yellow Ground, 12.20mm (.480") Diameter, 100.0m (328.08') Length, Orange

Documents:

[Product Specification 1553210001-P1E \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Brochure \(PDF\)](#)

Agency Certification

UL E172949

General

Product Family	Cable
Series	155321
Crimp Quality Equipment	Yes
Geographic Area	Global
Overview	Flamar Standard and Custom Cables for Industrial Automation
Product Name	Flamar, Servo Motor
UPC	889056460392

Physical

Bending Radius - Minimum	> 10xOD
Cable Length	100.0m
Circuits (Loaded)	4
Color - Cable Jacket	Orange
Insulation	TPE
Material - Outer Jacket	WSOR
Net Weight	0.288/kg
Outer Jacket Diameter	12.20mm
Packaging Type	Reel
Temperature Range - Operating	-25° to +80°C
Wire Size AWG	12
Wire Size mm ²	4.00
Wire/Cable Type	UL AWM 21939 / CSA

Electrical


Current - Maximum per Contact	Contact Molex
Voltage - Maximum	1000V

Material Info

Engineering Number	1X100M
--------------------	--------

Reference - Drawing Numbers

Product Specification	1553210001-P1E
-----------------------	----------------

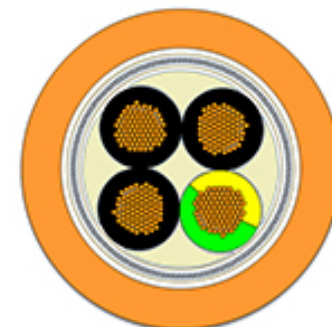

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Missing Compliance Data

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Reviewed

RoHS Phthalates

Missing Compliance Data

Search Parts in this Series

[155321](#) Series

Use With

Brad M23 [120230](#) , [120233](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155321-0007](#)