


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1553212004](#)
Status: **Active**
Overview: Flamar Standard and Custom Cables for Industrial Automation
Description: Flamar Power Cable, WSOR Jacket, Braided Shielding Overall, 8 Circuits, 4x(2.50mm²) with Green-Yellow Ground + 2x(2x1.00mm² with Braided Shield) / 4x(14 AWG) with Green-Yellow Ground + 2x(2x18 AWG with Braided Shield), 14.10mm (.555") Diameter, 100.0m (328.08') Length, Orange

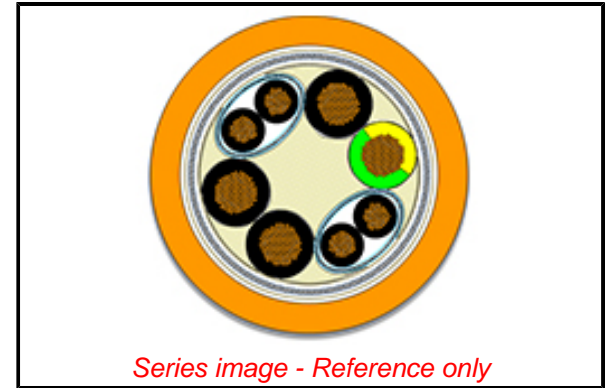

Documents:

[Product Specification 1553210001-P1E \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

UL E172949

General

Product Family Cable
Series [155321](#)
Crimp Quality Equipment Yes
Geographic Area Global
Overview [Flamar Standard and Custom Cables for Industrial Automation](#)
Product Name Flamar, Servo Motor
UPC 889056460804

Physical

Bending Radius - Minimum > 10xOD
Cable Length 100.0m
Circuits (Loaded) 8 (4+2+2)
Color - Cable Jacket Orange
Insulation TPE
Material - Outer Jacket WSOR
Net Weight 0.320/kg
Outer Jacket Diameter 14.10mm
Packaging Type Reel
Temperature Range - Operating -25° to +80°C
Wire Size AWG 14, 18
Wire Size mm² 1.00, 2.50
Wire/Cable Type UL AWM 21939 / CSA

Electrical

Current - Maximum per Contact Contact Molex
Voltage - Maximum 1000V

Material Info

Engineering Number 1X100M

Reference - Drawing Numbers

Product Specification 1553210001-P1E

EU ELV

Not Reviewed

EU RoHS

Missing Compliance Data

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Reviewed

RoHS Phthalates

Missing Compliance Data

Search Parts in this Series

[155321](#) Series

Use With

Brad M23 [120230](#) , [120233](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155321-2004](#)