

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1553310006](#)

Status: **Active**

Overview: Flamar Standard and Custom Cables for Industrial Automation

Description: Flamar Power Cable, PUR Jacket, Braided Shielding Overall, 4 Circuits, 2.50mm² with Green-Yellow Ground / 14 AWG with Green-Yellow Ground, 10.60mm (.417") Diameter, 1000.0m (3280.83') Length, Orange

Documents:

[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	155331
Crimp Quality Equipment	Yes
Geographic Area	Global
Overview	Flamar Standard and Custom Cables for Industrial Automation
Product Name	Flamar, Servo Motor
UPC	889056461368

Physical


Bending Radius - Minimum	> 10xOD
Cable Length	1000.0m
Circuits (Loaded)	4
Color - Cable Jacket	Orange
Insulation	TPE
Material - Outer Jacket	PUR
Net Weight	0.010/g
Outer Jacket Diameter	10.60mm
Packaging Type	Wooden Drum
Temperature Range - Operating	-40° to +80°C
Wire Size AWG	14
Wire Size mm ²	2.50
Wire/Cable Type	UL AWM 21223 / CSA

Electrical

Current - Maximum per Contact	Contact Molex
Voltage - Maximum	1000V

Material Info

Engineering Number	1X1000M
--------------------	---------

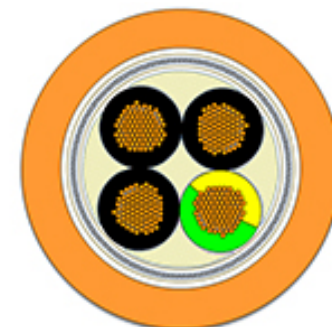

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

China RoHS

Search Parts in this Series

[155331](#) Series

Use With

Brad M23 [120230](#) , [120233](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155331-0006](#)