


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1553310010](#)

Status: **Active**

Overview: Flamar Standard and Custom Cables for Industrial Automation

Description: Flamar Power Cable, PUR Jacket, Braided Shielding Overall, 4 Circuits, 6.00mm² with Green-Yellow Ground / 10 AWG with Green-Yellow Ground, 14.50mm (.177") Diameter, 100.0m (328.08') Length, Orange

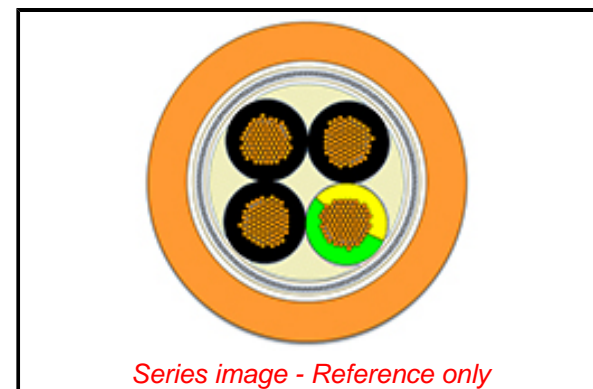

Series image - Reference only

Documents:

[Product Specification 1553310001-P1E \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Brochure \(PDF\)](#)

Agency Certification

UL E172949

General

Product Family	Cable
Series	155331
Crimp Quality Equipment	Yes
Geographic Area	Global
Overview	Flamar Standard and Custom Cables for Industrial Automation
Product Name	Flamar, Servo Motor
UPC	889056461405

Physical

Bending Radius - Minimum	> 10xOD
Cable Length	100.0m
Circuits (Loaded)	4
Color - Cable Jacket	Orange
Insulation	TPE
Material - Outer Jacket	PUR
Net Weight	0.377/kg
Outer Jacket Diameter	14.50mm
Packaging Type	Reel
Temperature Range - Operating	-40° to +80°C
Wire Size AWG	10
Wire Size mm ²	6.00
Wire/Cable Type	UL AWM 21223 / CSA

Electrical

Current - Maximum per Contact	Contact Molex
Voltage - Maximum	1000V

Material Info

Engineering Number	1X100M
--------------------	--------

Reference - Drawing Numbers

Product Specification	1553310001-P1E
-----------------------	----------------

EU ELV

Not Reviewed

EU RoHS

Missing Compliance Data

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Reviewed

RoHS Phthalates

Missing Compliance Data

Search Parts in this Series

[155331 Series](#)

Use With

Brad M23 [120230](#) , [120233](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155331-0010](#)