

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1553310012](#)
Status: **Active**
Overview: Flamar Standard and Custom Cables for Industrial Automation
Description: Flamar Power Cable, PUR Jacket, Braided Shielding Overall, 4 Circuits, 6.00mm² with Green-Yellow Ground / 10 AWG with Green-Yellow Ground, 14.50mm (.177") Diameter, 1000.0m (3280.83') Length, Orange

Documents:

[Product Specification 1553310001-P1E \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

UL E172949

General

Product Family Cable
 Series [155331](#)
 Crimp Quality Equipment Yes
 Geographic Area Global
 Overview [Flamar Standard and Custom Cables for Industrial Automation](#)
 Product Name Flamar, Servo Motor
 UPC 889056461528

Physical

Bending Radius - Minimum > 10xOD
 Cable Length 1000.0m
 Circuits (Loaded) 4
 Color - Cable Jacket Orange
 Insulation TPE
 Material - Outer Jacket PUR
 Net Weight 0.377/kg
 Outer Jacket Diameter 14.50mm
 Packaging Type Wooden Drum
 Temperature Range - Operating -40° to +80°C
 Wire Size AWG 10
 Wire Size mm² 6.00
 Wire/Cable Type UL AWM 21223 / CSA

Electrical


Current - Maximum per Contact Contact Molex
 Voltage - Maximum 1000V

Material Info

Engineering Number 1X1000M

Reference - Drawing Numbers

Product Specification 1553310001-P1E

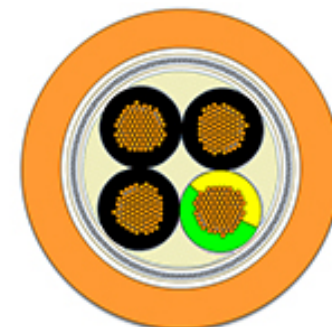

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Missing Compliance Data

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Reviewed

RoHS Phthalates

Missing Compliance Data

Search Parts in this Series

[155331 Series](#)

Use With

Brad M23 [120230](#) , [120233](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155331-0012](#)