

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1554212001](#)
Status: **Active**
Overview: Flamar Standard and Custom Cables for Industrial Automation
Description: Flamar CC-Link Network Cable, WSOR Jacket, Braided Shielding Overall, 3 Circuits, 0.50mm² / 20 AWG, 7.70mm (.303") Diameter, 300.0m (984.25') Length, Red

Documents:

[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	155421
Comments	3 reels of 100.0m each
Crimp Quality Equipment	Yes
Geographic Area	Global
Overview	Flamar Standard and Custom Cables for Industrial Automation
Product Name	Flamar, Network
Protocol	CC-Link
UPC	889056464185

Physical


Bending Radius - Minimum	> 15xOD
Cable Length	300.0m
Circuits (Loaded)	3
Color - Cable Jacket	Red
Insulation	Foam PE
Material - Outer Jacket	WSOR
Net Weight	0.010/g
Outer Jacket Diameter	7.70mm
Packaging Type	Reel
Temperature Range - Operating	-10° to +60°C
Wire Size AWG	20
Wire Size mm ²	0.50
Wire/Cable Type	UL AWM 21215 / CSA

Electrical

Current - Maximum per Contact	Contact Molex
Voltage - Maximum	600V

Material Info

Engineering Number	3X100M
--------------------	--------

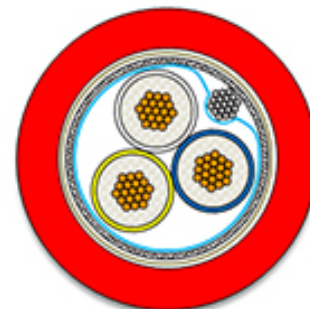

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[155421](#) Series

Use With

Micro-Change (M12) [130047](#) , [120100](#) , [130034](#) , [120071](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[155421-2001](#)