

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1721590503](#)
Status: **Active**
Overview: [EdgeMate Wire-to-Edge-Card Power Connector](#)
Description: 3.96mm Pitch EdgeMate Wire-to-Board Edge Card Connector, Female, Nylon 6/6, White, UL94-V2, with Positive Lock, 3 Circuits

Documents:

[3D Model](#) [Product Specification PS-172160-0001-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Packaging Specification PK-172159-0001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Edge Card Connectors
 Series [172159](#)
 Comments See Product Specification for maximum current rating by wire AWG and terminal material.
 Component Type Edgecard to Wire
 Data Rate Unrated
 Edge Card Thickness N/A
 High Power Bay (30.0A or more) No
 Orientation Right-Angle
 Overview [EdgeMate Wire-to-Edge-Card Power Connector](#)
 Product Name EdgeMate
 Standard Based General
 UPC 887191569826

Physical


(p)ower-(s)ignal Configuration 3p - 0s
 Circuit Size Range 1-64 Circuits
 Circuits (Loaded) 3
 Circuits (maximum) 3
 Color - Resin White
 Durability (mating cycles max) 25
 Entry Angle 90° Angle
 Flammability 94V-2
 Keying to Mating Part None
 Material - Plating Mating N/A
 Material - Resin Nylon
 Net Weight 1.660/g
 PCB Locator Yes
 PCB Retention Yes
 PCB Thickness - Recommended 1.57mm
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 3.96mm
 Polarized to Mating Part No
 Temperature Range - Operating -40° to +105°C, -40° to +80°C
 Termination Interface: Style Straddle Mount-Edge Card

Electrical

Current - Maximum per Contact 7.0A
 Voltage - Maximum 250V

Solder Process Data

Lead-freeProcess Capability N/A

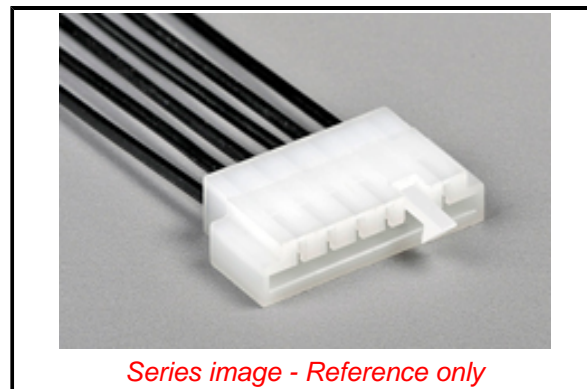

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2020)9139-DC (19
 Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[172159 Series](#)

Mates With

Edge Card PCB

Use With

[172160](#)

Material Info

Reference - Drawing Numbers

Packaging Specification

PK-172159-0001-001

Product Specification

PS-172160-0001-001

Sales Drawing

SD-172159-0002-000

This document was generated on 03/03/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[172159-0503](#)