


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1725103612](#)  
**Status:** **Active**  
**Overview:** [EXTreme Ten60Power High-Current Connector](#)  
**Description:** EXTreme Ten60Power Wire-to-Board Receptacle Housing, 12 Signal Circuits, 6 Power Circuits

**Documents:**

<a href="#">3D Model (PDF)</a>	<a href="#">Packaging Specification PK-172510-0001-001 (PDF)</a>
<a href="#">3D Model</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-173693-001-001 (PDF)</a>	

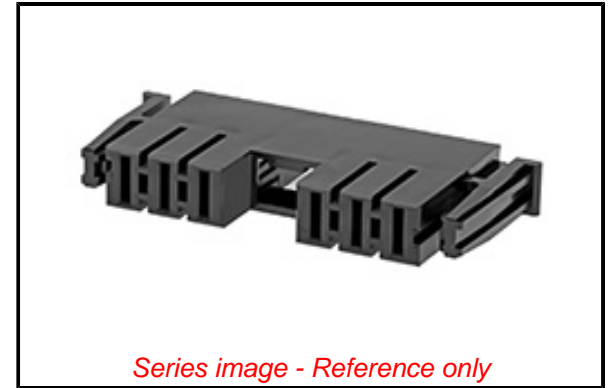

**General**

Product Family	Crimp Housings
Series	<a href="#">172510</a>
Application	Power, Signal, Wire-to-Board
Overview	<a href="#">EXTreme Ten60Power High-Current Connector</a>
Product Name	EXTreme Ten60Power
UPC	889056280662

**Physical**

Circuits (maximum)	18
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	14.880/g
Number of Rows	1, 3
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	2.54mm, 7.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

**Electrical**

Current - Maximum per Contact	2.5A, 55.0A
-------------------------------	-------------

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-172510-0001-001
Product Specification	PS-173693-001-001
Sales Drawing	SD-172510-001-001

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[172510 Series](#)

**Mates With**

EXTreme Ten60Power PCB Header  
[1724530612](#)

**Use With**

TPA Retainer [46708](#) , Signal Housing [46709](#)  
, Power Terminal [173693](#) , Signal Terminal  
[70058](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[172510-3612](#)