

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731090035](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT High-Density D-Sub Crimp Housing, Male, 15 Circuits

Documents:

[Datasheet \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	D-Sub Products
Series	173109
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	High Density
UPC	889056291194

Physical


Circuits (Loaded)	0
Circuits (maximum)	15
Color - Resin	Black
Durability (mating cycles max)	500
Gender	Male
Material - Resin	PBT
Material - Shell	Steel
Net Weight	4.300/g
Number of Rows	3
Orientation	Straight
PCB Locator	No
PCB Retention	None
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	1.98mm
Pitch - Termination Interface	1.98mm
Plating - Shell	Tin
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +105°C
Termination Style	Crimp
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size AWG	22, 24, 26, 28

Material Info

Engineering Number FL09-15P7

Reference - Drawing Numbers

Sales Drawing 1731090035-000

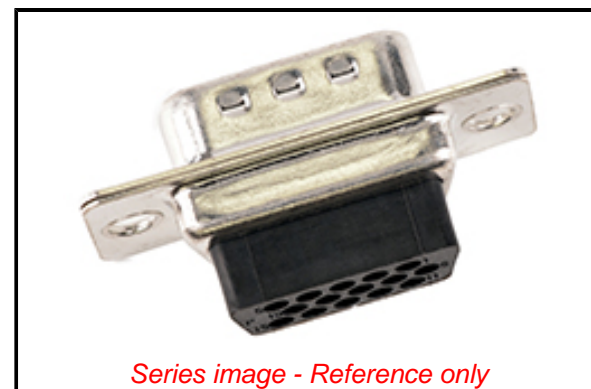

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[173109 Series](#)

Mates With

FCT High-Density D-Sub, Size 1, 15
Position, Socket

Use With

FCT High-Density Male Crimp Contacts
[1731120223](#) , [1731120224](#) , [1731120225](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[173109-0035](#)