

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2001220012](#)
Status: **Active**
Overview: [Mega-Fit Power Connectors](#)
Description: Mega-Fit Receptacle Backshell, Dual Row, Low-Halogen, 12 Circuits

Documents:

Drawing (PDF)	Application Specification AS-76823-100-001 (PDF)
3D Model	RoHS Certificate of Compliance (PDF)
3D Model (PDF)	

General

Product Family	Accessories
Series	200122
Component Type	Backshell
Overview	Mega-Fit Power Connectors
Product Name	Mega-Fit
UPC	889056290999

Physical

Circuits (Loaded)	12
Circuits (maximum)	12
Color - Resin	Black
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	4.260/g
Number of Rows	2
Packaging Type	Bag
Temperature Range - Operating	-40° to +105°C

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	F4068.06-P27
--------------------	--------------

Reference - Drawing Numbers

Application Specification	AS-76823-100-001
Sales Drawing	2001220000-SD-000

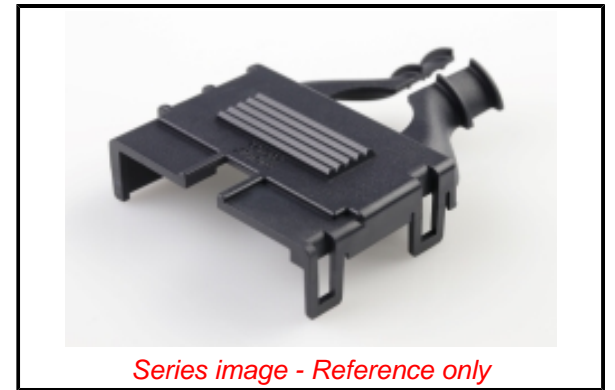

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[200122 Series](#)

Use With

Mega-Fit Receptacle Housing [171692](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[200122-0012](#)