

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2451320899](#)
Status: **Active**
Overview: [Micro-Fit Connector System](#)
Description: Micro-Fit 3.0 Overmolded Plug Adapter, Dual Row, 8 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	245132
Application	Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Micro-Fit 3.0 Both Ends
Overmolded	Yes
Overview	Micro-Fit Connector System
Product Name	Micro-Fit 3.0
Type	Plug Adapter
UPC	191128755214

Physical

Cable Length	50.00mm
Circuits (Loaded)	8
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon, PBT
Net Weight	42.034/g
Number of Rows	2
Packaging Type	Bag
Pitch - Mating Interface	3.00mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.76mm
Wire Size AWG	20
Wire/Cable Type	UL 1007


Electrical

Current - Maximum per Contact	5.6A
Voltage - Maximum	300V DC

Material Info

Reference - Drawing Numbers

Sales Drawing	2014400171-001
---------------	----------------

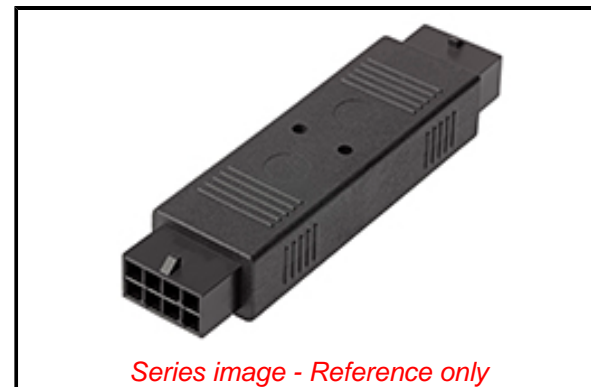

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[245132](#) Series

Mates With

Micro-Fit 3.0 Receptacle Housings [43025](#) ,

Micro-Fit 3.0 Cable Assembly [245132](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[245132-0899](#)