

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300950257](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Medium Duty Wire Mesh Slack Grip Cable, Split Rod, Single Weave, Offset Eye, Medium Mesh Length 0.305m (12.00"), Approximate Break Strength 1859.73kg (4100 lbs)

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
 Series [130095](#)
 Eye Type Offset
 O-Ring N/A
 Overview [Support Grips](#)
 Product Name Medium Duty
 Type Pulling Grip
 UPC 78678836143

Physical


Approximate Break Strength 1859.73kg (4100 lbs)
 Bale Length N/A
 Body Style Straight
 Cable Diameter 25.40-31.50mm (1.000-1.240")
 Color - Grommet N/A
 Gender N/A
 Material - Body N/A
 Material - Grip Galvanized Steel
 Mesh Length 0.305m (12.00")
 Number of Holes N/A
 Thread Size N/A

Material Info

Engineering Number 36143

Reference - Drawing Numbers

Sales Drawing SD-130095-112

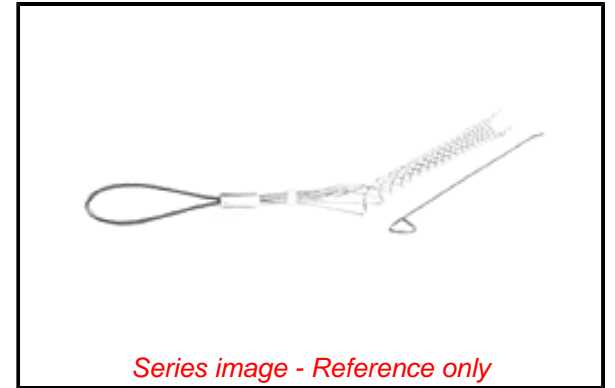

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130095 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1300950257](#) [36143](#)