

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301470068](#)  
**Status:** **Active**  
**Overview:** [Watertite Extreme Wet-Location Wiring Solutions](#)  
**Description:** [Watertite Extreme Connector for Male Receptacle with Locking Blade, Single Flip Coverplate, 4 Pole/5 Wire, NEMA L23-20, 3Ø 600V, F3](#)

**Documents:**

[Drawing \(PDF\)](#)  
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837

**General**

Product Family	Wiring Devices
Series	<a href="#">130147</a>
IP Rating	IP67
NEMA Configuration	NEMA L23-20
Overview	<a href="#">Watertite Extreme Wet-Location Wiring Solutions</a>
Product Name	Watertite Extreme
Receptacle Type	Single
Specialty	N/A
Type	Connector
UPC	78678871381

**Physical**

Cord Grip Body Size	F3 3/4"
Flange	No
Flip Lid	No
Gender	Female
Length	N/A
Locking Blade	Yes
Poles	4-pole/5-wire

**Electrical**


Cord Type	N/A
Current - Maximum per Contact	20.0A
GFCI	No
Lighted Connector	No
Voltage - Maximum	3Ø 600V

**Material Info**

Engineering Number 27W83MB

**Reference - Drawing Numbers**

Sales Drawing 1301470068-000

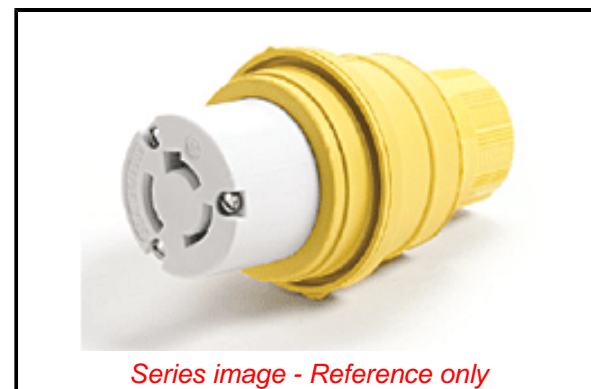

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130147 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1301470068](#) [27W83MB](#)