

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150140431](#)
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.25mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Gold (Au) Plating, 31 Circuits

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 1501400001-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Cable
 Series [15014](#)
 Crimp Quality Equipment Yes
 Overview [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
 Product Name Premo-Flex FFC Jumper
 UPC 191130093434

Physical

Cable Length 102.00mm
 Circuits (Loaded) 31
 Contact Layout Type A (same side)
 Material - Plating Mating Gold
 Net Weight 1.000/g
 Packaging Type Bag
 Pitch - Mating Interface 0.25mm
 Temperature Range - Operating -40° to +105°C
 Wire Size AWG N/A
 Wire/Cable Type Flat Flex Cable


Electrical

Current - Maximum per Contact 0.2A
 Voltage - Maximum N/A

Material Info

Reference - Drawing Numbers

Product Specification 1501400001-000
 Sales Drawing 150140001-000

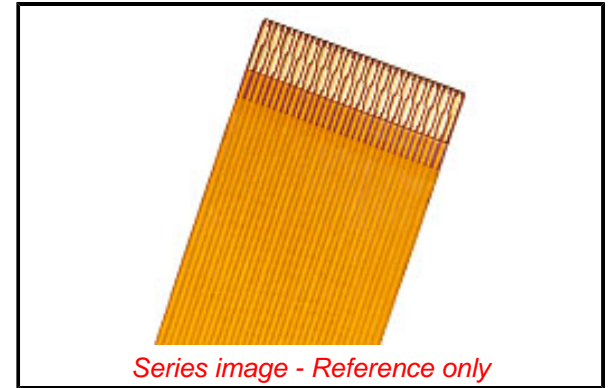

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2021)4569-DC (8
 July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[15014 Series](#)

Mates With

Easy-On FFC/FPC Connector [5033003110](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15014-0431](#)