

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0150181025**
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.50mm Pitch Premo-Flex FFC Jumper with Ears, Same Side Contacts (Type A), 229.00mm Cable Length, Gold (Au) Plating, 31 Circuits

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 150180001-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|-------------------------|---|
| Product Family | Cable |
| Series | 15018 |
| Comments | Same Side Contacts, Type A |
| Crimp Quality Equipment | Yes |
| Overview | FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers |
| Product Name | Premo-Flex FFC Jumper |
| UPC | 193264336180 |

Physical

| | |
|-------------------------------|-----------------|
| Cable Length | 229.00mm |
| Circuits (Loaded) | 31 |
| Contact Layout Type | A (same side) |
| Material - Plating Mating | Gold |
| Packaging Type | Bag |
| Pitch - Mating Interface | 0.50mm |
| Temperature Range - Operating | -40° to +105°C |
| Wire Size AWG | N/A |
| Wire/Cable Type | Flat Flex Cable |


Electrical

| | |
|-------------------------------|--------|
| Current - Maximum per Contact | 0.5A |
| Voltage - Maximum | 60V AC |

Material Info

Reference - Drawing Numbers

| | |
|-----------------------|------------------|
| Product Specification | 150180001-000 |
| Sales Drawing | SD-15018-001-001 |

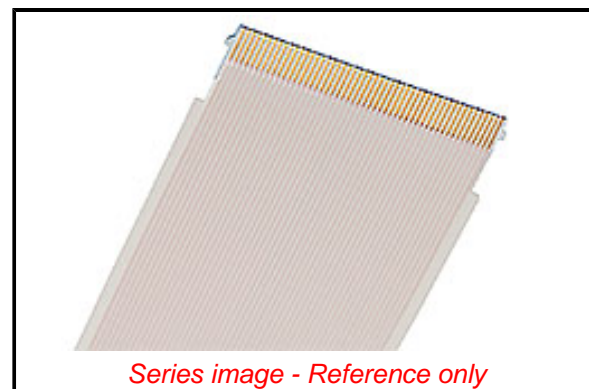

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

15018 Series

Mates With

Easy-On FFC/FPC Connector [5051103191](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15018-1025](#)