

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0936060150](#)  
**Status:** **Active**  
**Overview:** GWconnect Heavy Duty Connectors (HDC)  
**Description:** GWconnect Patch Cord Cable Assembly, CAT5 (CAT5e) Plug-to-Plug, 8P4C Wiring, Fully Shielded, 2.0m

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**


Product Family	Industrial Connectors / Enclosures
Series	<a href="#">93606</a>
Color - Cable Jacket	Grey
Comments	Class D up to 100 MHz acc. to ISO/IEC 11802
Component Type	Cable Assembly
IP Rating	IP20
Length	2.0m
Material - Outer Jacket	PVC
Overview	<a href="#">GWconnect Heavy Duty Connectors (HDC)</a>
Product Category	Patch Cords
Product Name	GWconnect
Standard	EN 50173-1
Type	RJ45 CAT5
UPC	887191839073

**Physical**

Cable Diameter	6.90mm
Gender	Plug/Plug
Lock to Mating Part	Yes
Material - Plating	Gold
Material - Plug	PBT
Net Weight	79.200/g
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	8p/4C
Temperature Range - Operating	-20° to +70°C
Wire Size AWG	24

**Material Info**

Engineering Number	2240.3244.2
--------------------	-------------

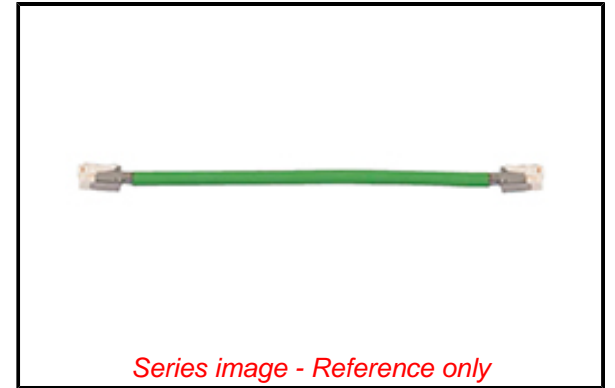

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[93606 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93606-0150](#)