

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936060198](#)
Status: **Active**
Overview: GWconnect® Heavy Duty Connectors (HDC)
Description: GWconnect Patch Cord Cable Assembly, CAT5 (CAT5e) Plug-to-Plug, 8P4C + 2PC Wiring, Black Boot, Fully Shielded, 1.0m

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Industrial Connectors / Enclosures
Series	93606
Boot	Yes
Boot Color	Black
Color - Cable Jacket	Green
Comments	Class D up to 100 MHz acc. to ISO/IEC 11802
Component Type	Cable Assembly
IP Rating	IP20
Length	1.0m
Material - Outer Jacket	PUR
Overview	GWconnect® Heavy Duty Connectors (HDC)
Product Category	Patch Cords
Product Name	GWconnect
Standard	EN 50173-1
Type	RJ45 CAT5
UPC	887191842349

Physical

Cable Diameter	6.80mm
Gender	Plug/Plug
Lock to Mating Part	Yes
Material - Plating	Gold
Material - Plug	PBT
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	8p/4C + 2pC
Temperature Range - Operating	-20°C to +70°C
Wire Size AWG	22, 26

Material Info

Engineering Number	2342.3246.1
--------------------	-------------

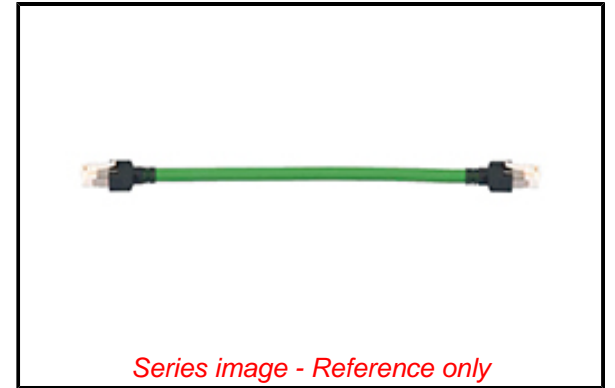

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[93606 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93606-0198](#)