

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1000570053](#)  
**Status:** **Active**  
**Overview:** Temp-Flex Flat Ribbon Cable Solutions  
**Description:** Temp-Flex High-Performance Flat-Ribbon Cable, 26 Circuits, 1.27mm Pitch, 28 AWG, Silver Plated Copper, UL 20424, 7/36 Stranded Extruded FEP, Red

**Documents:**

[Drawing \(PDF\)](#) [Brochure \(PDF\)](#)  
[Datasheet \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable
Series	<a href="#">100057</a>
Crimp Quality Equipment	Yes
Overview	<a href="#">Temp-Flex Flat Ribbon Cable Solutions</a>
Product Name	Temp-Flex
UPC	889056597357

**Physical**

Cable Length	100 ft/spool, 10 ft min length
Circuits (Loaded)	26
Color - Cable Jacket	Red
Insulation	FEP
Material - Outer Jacket	FEP
Material - Plating Mating	Silver
Net Weight	22.833/g
Packaging Type	Spool
Pitch - Mating Interface	1.27mm
Temperature Range - Operating	-65° to +200°C
Wire Size AWG	28
Wire/Cable Type	7/36 Stranded, High-Performance Flat-Ribbon, UL 20424

**Electrical**


Current - Maximum per Contact	1.5A
Voltage - Maximum	300V AC

**Material Info**

Engineering Number	F2807S-26-050-1
--------------------	-----------------

**Reference - Drawing Numbers**

Sales Drawing	1000572807RED-000
---------------	-------------------

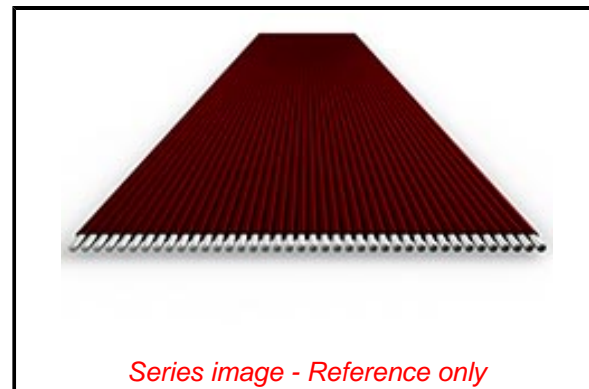

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[100057 Series](#)

**Use With**

Molex Picoflex

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[100057-0053](#)