

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1000570265](#)
Status: **Active**
Overview: [Temp-Flex Flat Ribbon Cable Solutions](#)
Description: Temp-Flex High-Performance Flat-Ribbon Cable, 40 Circuits, 0.64mm Pitch, 30 AWG, Silver Plated Copper, UL 20726 Solid Extruded FEP, Natural with Blue Polarity Stripe

Documents:

[Drawing \(PDF\)](#) [Brochure \(PDF\)](#)
[Datasheet \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	100057
Crimp Quality Equipment	Yes
Overview	Temp-Flex Flat Ribbon Cable Solutions
Product Name	Temp-Flex
UPC	889056603843

Physical

Cable Length	100 ft/spool, 10 ft min length
Circuits (Loaded)	40
Color - Cable Jacket	Natural w/Blue Polarity Stripe
Insulation	FEP
Material - Outer Jacket	FEP
Material - Plating Mating	Silver
Net Weight	18.351/g
Packaging Type	Spool
Pitch - Mating Interface	0.64mm
Temperature Range - Operating	-65° to +150°C
Wire Size AWG	30
Wire/Cable Type	High-Performance Flat-Ribbon, Solid Extruded FEP, UL 20726

Electrical


Current - Maximum per Contact	1.0A
Voltage - Maximum	150V AC

Material Info

Engineering Number	F3001S-40-025-85
--------------------	------------------

Reference - Drawing Numbers

Sales Drawing	1000573001NBST-000
---------------	--------------------

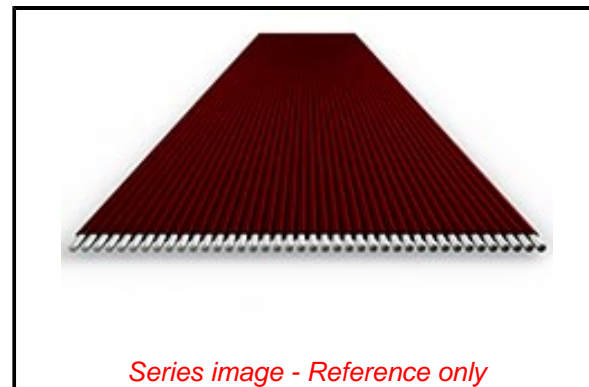

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[100057 Series](#)

Use With

Molex Picoflex

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[100057-0265](#)