

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300250048](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change Double-Ended Cordset, 5 Poles, Male (Straight) to Female (Straight), 15 and 18 AWG, DeviceNet Thick (Trunk) Cable, 0.305m (1.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130025](#)
 Connector End A Mini-Change
 Connector End B Mini-Change
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [Brad Mini-Change Connectors](#)
 Product Name DeviceNet Trunk, Mini-Change
 Region Europe
 Type Double Ended
 UPC 78678847701

Physical

Cable Diameter 12.10mm (.480")
 Cable Length 0.30m (11.81")
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Die-Cast Zinc
 Material - Plating Mating Gold
 Net Weight 97.470/g
 Orientation Straight to Straight
 Poles 5
 Temperature Range - Operating -20° to +80°C
 Wire Size AWG 15, 18
 Wire/Cable Type Thick (Trunk)

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 300V AC/DC

Material Info

Engineering Number DN11A-M003

Reference - Drawing Numbers

Sales Drawing SD-130025-001-001

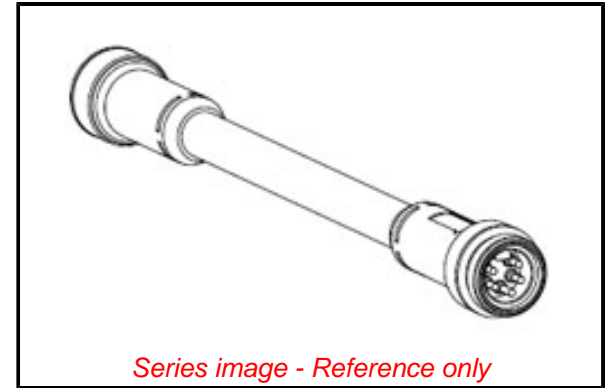

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130025 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300250048](#)