

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300460001](#)  
**Status:** **Active**  
**Overview:** [Brad Micro-Change \(M12\) Connectors](#)  
**Description:** [Micro-Change Male Terminator Resistor with CC-Link Connection, 4 Pole](#)

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Field Attachable / Accessories
Series	<a href="#">130076</a>
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	<a href="#">Brad Micro-Change (M12) Connectors</a>
Product Name	CC-Link, Micro-Change (M12)
Type	Termination Resistor
UPC	78678861903

**Physical**

Cable Diameter	N/A
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	Single
Material - Connector Body	PVC
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold
Net Weight	17.141/g
Orientation	Straight
Poles	4
Temperature Range - Operating	0°C to +60°C
Wire Size AWG	N/A

**Electrical**


Current - Maximum per Contact	0.05A
Voltage - Maximum	24V DC

**Material Info**

Engineering Number	CC100
--------------------	-------

**Reference - Drawing Numbers**

Sales Drawing	CC100, SD-130046-013
---------------	----------------------

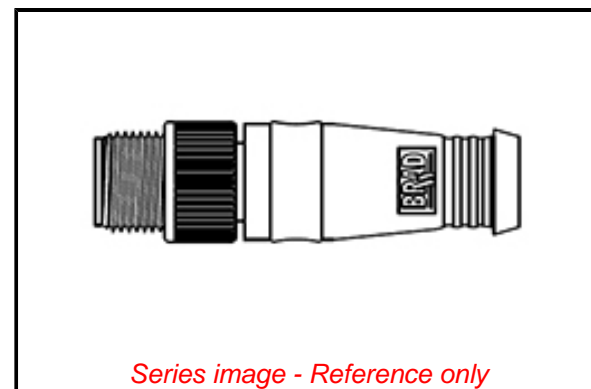

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per -  
D(2020)9139-DC (19  
Jan 2021)

lead

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[130076 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300460001](#)