

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300970271](#)  
**Status:** **Active**  
**Overview:** Strain-Relief Cord Grips  
**Description:** Dust-Tight Strain Relief Wide Range Grip, 1-1/2" NPT, Straight Male, Cable Diameter 30.48-38.10mm (1.200-1.500"), Approximate Break Strength 453.59kg (1400 lbs)

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Brochure \(PDF\)](#)

**Agency Certification**

CSA LR32159  
 UL E76954

**General**

Product Family Cable Grips  
 Series [130097](#)  
 Eye Type N/A  
 Insulated Yes  
 NEMA Rating Dust Tight  
 O-Ring N/A  
 Overview [Strain-Relief Cord Grips](#)  
 Product Name Dust-Tight  
 Type Strain Relief Grip  
 UPC 78678836516

**Physical**


Approximate Break Strength 453.59kg (1400 lbs)  
 Bale Length N/A  
 Body Style Straight  
 Cable Diameter 30.48-38.10mm (1.200-1.500")  
 Color - Grommet N/A  
 Gender Male  
 Material - Body Zinc Plated Steel  
 Material - Grip Galvanized Steel  
 Mesh Length 0.298m (11.50")  
 Number of Holes N/A  
 Thread Size 1 1/2" NPT

**Material Info**

Engineering Number 36516

**Reference - Drawing Numbers**

Sales Drawing SD-130097-002

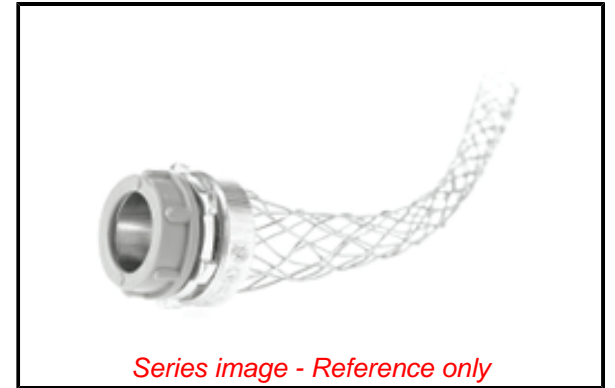

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130097 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[1300970271](#)