

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1727040134](#)
Status: **Active**
Overview: FCT D-Sub Connectors
Description: FCT High Voltage Contact, Male, Straight, Solder Cup, 0.80µm Gold Plating, 20 AWG or smaller

Documents:

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	D-Sub Products
Series	172704
Contact Type	High Voltage
Overview	<u>FCT D-Sub Connectors</u>
Product Category	Contacts
Product Name	FCT Products
Type	Mixed Layout
UPC	889056020459

Physical


Durability (mating cycles max)	500
Gender	Male
Material - Contact	Copper Alloy
Material - Insulator	PTFE
Material - Retaining Clip	PEI
Net Weight	0.700/g
Orientation	Straight
Packaging Type	Bag
Plating - Contact	Gold over Nickel
Plating min - Mating	0.800µm
Plating min - Termination	0.800µm
Temperature Range - Operating	-55° to +125°C
Termination Style	Solder Cup
Wire Size AWG	20

Electrical

Current - Maximum per Contact	2.0A
-------------------------------	------

Material Info

Engineering Number	FMV001P107K
--------------------	-------------

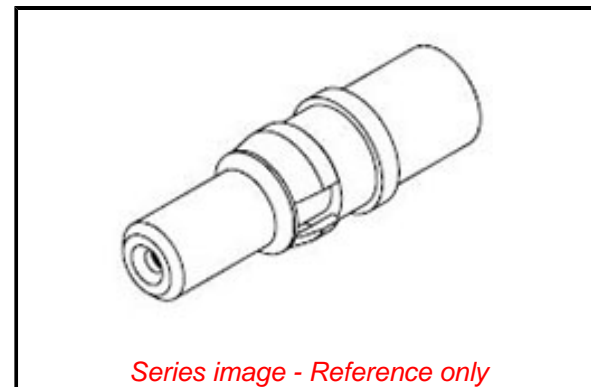

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)

Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[172704 Series](#)

Use With

FCT Mixed Layout Connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[172704-0134](#)