

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2064610600](#)
Status: **Active**
Overview: [Micro-Fit+ Connector System](#)
Description: Micro-Fit+ Receptacle Housing, Dual Row, 6 Circuits, UL 94V-0, Glow-Wire Capable, Black

Documents:

3D Model	Packaging Specification 2064610000-PK-000 (PDF)
3D Model (PDF)	Test Summary 2064600000-TS-000 (PDF)
Drawing (PDF)	Datasheet (PDF)
Product Specification 2064600000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	206461
Application	Power, Wire-to-Board
Overview	Micro-Fit+ Connector System
Product Name	Micro-Fit+
UPC	191130004027


Physical

Circuits (maximum)	6
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.713/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.00mm
Pitch - Termination Interface	3.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification	2064610000-PK-000
Product Specification	2064600000-PS-000
Sales Drawing	2064610000-SD-000
Test Summary	2064600000-TS-000

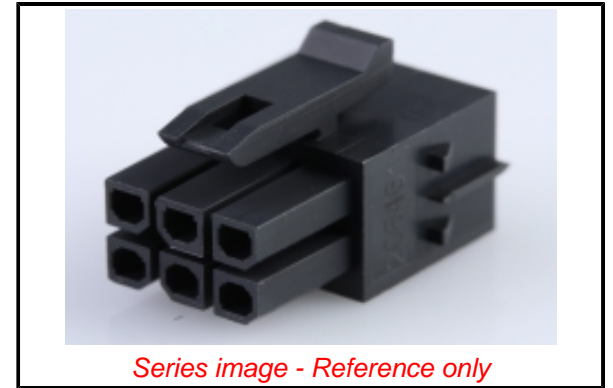

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[206461](#) Series

Mates With

Micro-Fit+ Headers [206832](#) , [212528](#)

Use With

Micro-Fit+ Female Terminal [206460](#)

Micro-Fit+ TPA [206462](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[206461-0600](#)