

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2073721002](#)
Status: **Active**
Overview: SlimSAS Connectors and Cable Assemblies
Description: SlimSAS Cable Assembly, PCIe 4.0, Straight Plug-to-Right-Angle Plug, 4x (38 Circuits), 32 AWG, 1.0m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Application Specification 2073680002-000 \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	207372
Assembly Configuration	Dual Ended Connectors
Connector to Connector	SlimSAS-to-SlimSAS
Overview	SlimSAS Connectors and Cable Assemblies
Product Name	SlimSAS
UPC	191130022793

Physical

Cable Length	1.0m
Circuits (Loaded)	38
Color - Resin	Black
Gender	Plug/Plug
Lock to Mating Part	Yes
Material - Resin	Polycarbonate
Net Weight	37.600/g
Packaging Type	Bag
Single Ended	No
Wire Size AWG	32
Wire/Cable Type	Ribbon Cable


Electrical

Current - Maximum per Contact	0.5A
Impedance	85Ω
Voltage - Maximum	30V AC

Material Info

Reference - Drawing Numbers

Application Specification	2073680002-000
Sales Drawing	2073701000-000

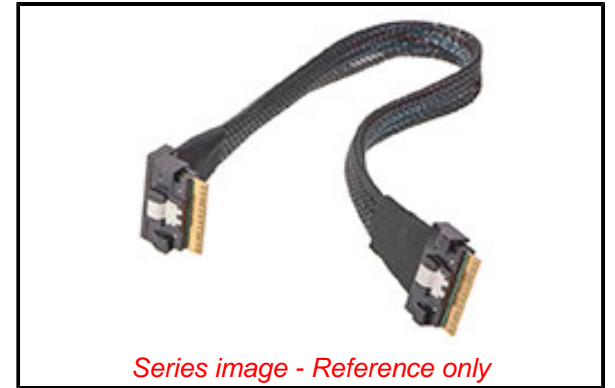

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[207372 Series](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[207372-1002](#)