


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2132261570](#)
Status: **Active**
Overview: [CLIK-Mate Wire-to-Board Connectors](#)
Description: 1.50mm Pitch CLIK-Mate Wire-to-Board PCB Receptacle, Single Row, Surface Mount, Right-Angle, 0.76µm Gold (Au) Plating, 15 Circuits, Natural

Documents:

| | |
|---|--|
| 3D Model | Product Specification 5025781004-PS-000 (PDF) |
| 3D Model (PDF) | Packaging Specification 2132269200-SPK-200 (PDF) |
| Drawing (PDF) | RoHS Certificate of Compliance (PDF) |
| Product Specification 5025780004-PS-000 (PDF) | |

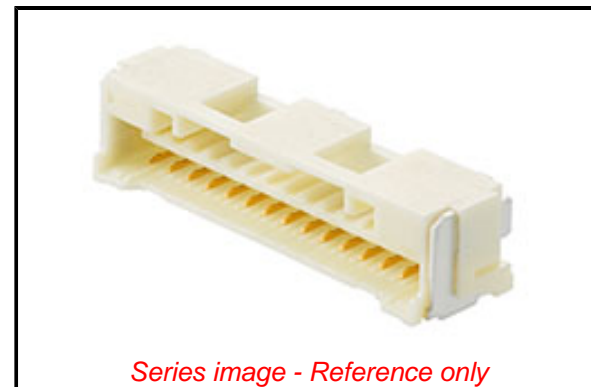

General

| | |
|----------------|--|
| Product Family | PCB Receptacles |
| Series | 213226 |
| Application | Signal, Wire-to-Board |
| Overview | CLIK-Mate Wire-to-Board Connectors |
| Product Name | CLIK-Mate |
| UPC | 193264242528 |

Physical

| | |
|--------------------------------|-----------------------|
| Circuits (Loaded) | 15 |
| Circuits (maximum) | 15 |
| Color - Resin | Natural |
| Durability (mating cycles max) | 30 |
| Glow-Wire Capable | No |
| Guide to Mating Part | Yes |
| Keying to Mating Part | Yes |
| Lock to Mating Part | Yes |
| Material - Metal | Copper Alloy |
| Material - Plating Mating | Gold |
| Material - Resin | Polyamide |
| Net Weight | 1007.000/mg |
| Number of Rows | 1 |
| Orientation | Right Angle |
| PCB Locator | No |
| PCB Retention | Yes |
| Packaging Type | Embossed Tape on Reel |
| Pitch - Mating Interface | 1.50mm |
| Pitch - Termination Interface | 1.50mm |
| Plating min - Mating | 0.762µm |
| Plating min - Termination | 0.762µm |
| Polarized to Mating Part | Yes |
| Polarized to PCB | No |
| Stackable | No |
| Surface Mount Compatible (SMC) | Yes |
| Temperature Range - Operating | -40° to +105°C |
| Termination Interface: Style | Surface Mount |

Electrical

| | |
|-------------------------------|------------------|
| Current - Maximum per Contact | 2.0A |
| Voltage - Maximum | 100V AC (RMS)/DC |

Material Info

Reference - Drawing Numbers

| | |
|-------------------------|--------------------------------------|
| Packaging Specification | 2132269200-SPK-200 |
| Product Specification | 5025780004-PS-000, 5025781004-PS-000 |

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[213226 Series](#)

Mates With

[CLIK-Mate Housing 502578](#)

This document was generated on 10/04/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[213226-1570](#)