

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2157112121](#)  
**Status:** **Active**  
**Overview:** [Off-the-Shelf Pre-Crimped Leads](#)  
**Description:** Pre-Crimped Lead Clik-Mate Male-to-Pigtail, Tin (Sn) Plating, 75.00mm Length, 24 AWG, Red

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Datasheet \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">215711</a>
Application	Signal, Wire-to-Board
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	CLIK-Mate Terminal-to-Pigtail
Overview	<a href="#">Off-the-Shelf Pre-Crimped Leads</a>
Product Name	CLIK-Mate
UPC	193264605316

**Physical**

Cable Length	75.00mm
Circuits (Loaded)	1
Color - Resin	Red
Gender	Male-Pigtail
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.320/g
Packaging Type	Bag
Plating min - Mating	0.406µm
Plating min - Termination	0.406µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.78-1.28mm
Wire Size AWG	24
Wire/Cable Type	UL 10002


**Electrical**

Current - Maximum per Contact	2.0A
Voltage - Maximum	100V AC (RMS)/DC

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	2157111121-000
---------------	----------------

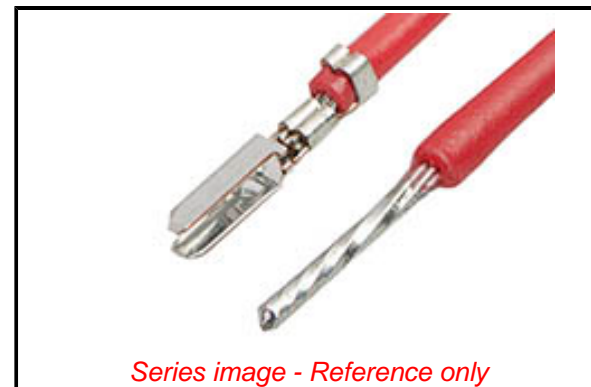

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[215711 Series](#)

**Use With**

[CLIK-Mate Housing 502578](#) , [503149](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[215711-2121](#)