

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2157603002](#)  
**Status:** **Active**  
**Overview:** [Micro-Fit+ Connector System](#)  
**Description:** Micro-Fit+ Right-Angle Header, 3.00mm Pitch, Single Row, 2 Circuits, 0.76µm Gold (Au) Plating, UL 94V-0, Glow-Wire Capable, Black

**Documents:**

[Drawing \(PDF\)](#)      [Test Summary 2157590005-TS-000 \(PDF\)](#)  
[Product Specification 2064600000-PS-000 \(PDF\)](#)      [RoHS Certificate of Compliance \(PDF\)](#)

**General**

|                |   |
|----------------|---|
| Product Family | PCB Headers                                 |
| Series         | <a href="#">215760</a>                      |
| Application    | Power, Wire-to-Board                        |
| Overview       | <a href="#">Micro-Fit+ Connector System</a> |
| Product Name   | Micro-Fit+                                  |
| UPC            | 193264937172                                |

**Physical**

|                                |                        |
|--------------------------------|------------------------|
| Breakaway                      | No                     |
| Circuits (Loaded)              | 2                      |
| Circuits (maximum)             | 2                      |
| Color - Resin                  | Black                  |
| Durability (mating cycles max) | 200                    |
| First Mate / Last Break        | No                     |
| Glow-Wire Capable              | Yes                    |
| Keying to Mating Part          | Yes                    |
| Lock to Mating Part            | Yes                    |
| Material - Metal               | High Copper Alloy      |
| Material - Plating Mating      | Gold                   |
| Material - Resin               | Liquid Crystal Polymer |
| Net Weight                     | 0.408/g                |
| Number of Rows                 | 1                      |
| Orientation                    | Right Angle            |
| PC Tail Length                 | 3.17mm                 |
| PCB Thickness - Recommended    | 1.57mm                 |
| Packaging Type                 | Tray                   |
| Pitch - Mating Interface       | 3.00mm                 |
| Pitch - Termination Interface  | 3.00mm                 |
| Plating min - Mating           | 0.762µm                |
| Polarized to Mating Part       | Yes                    |
| Polarized to PCB               | Yes                    |
| Shrouded                       | Yes                    |
| Temperature Range - Operating  | -40° to +105°C         |
| Termination Interface: Style   | Through Hole           |


**Electrical**

|                               |                  |
|-------------------------------|------------------|
| Current - Maximum per Contact | 12.5A            |
| Voltage - Maximum             | 600V AC (RMS)/DC |

**Material Info**

**Reference - Drawing Numbers**

|                       |                   |
|-----------------------|-------------------|
| Product Specification | 2064600000-PS-000 |
| Sales Drawing         | 2157600003-SD-000 |
| Test Summary          | 2157590005-TS-000 |

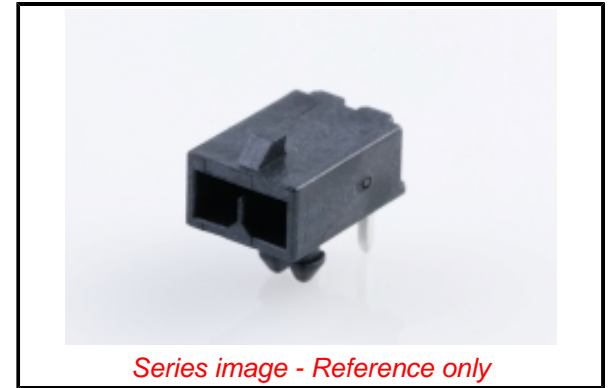

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[215760 Series](#)

**Mates With**

Micro-Fit+ Receptacle Housing [215759](#)

This document was generated on 12/20/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[215760-3002](#)