

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **2177932101**  
**Status:** **Active**  
**Overview:** Off-the-Shelf Pre-Crimped Leads  
**Description:** Pre-Crimped Lead Squba 1.8 Male-to-Pigtail, Tin (Sn) Plating, 75.00mm Length, 24 AWG, Red

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<u>217793</u>
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	Squba Crimp Terminals
Overview	<u>Off-the-Shelf Pre-Crimped Leads</u>
Product Name	Squba
UPC	195842124578

**Physical**

Cable Length	75.00mm
Circuits (Loaded)	1
Color - Resin	Red
Gender	Male-Pigtail
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	PVC
Net Weight	0.313/g
Number of Rows	1
Packaging Type	Bag
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.95mm-1.40mm
Wire Size AWG	24
Wire/Cable Type	UL 10002


**Electrical**

Current - Maximum per Contact	5.5A
Voltage - Maximum	125V

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	2177931101-000
---------------	----------------

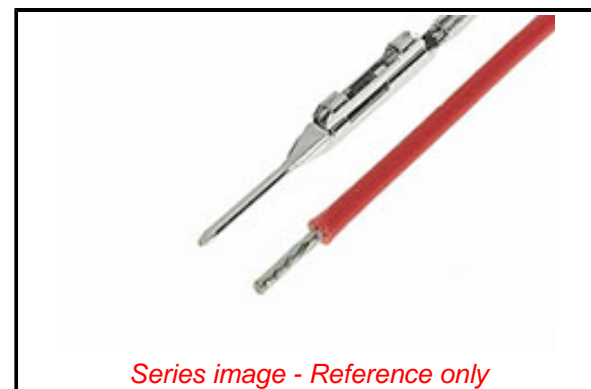

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

217793 Series

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[217793-2101](#)