

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **2181100903**  
**Status:** **Active**  
**Overview:** PicoBlade Connector System  
**Description:** PicoBlade Male-to-PicoBlade Male Off-the-Shelf (OTS) Cable Assembly, Single Row, 300.00mm Length, 9 Circuits, Natural

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<u>218110</u>
Application	Signal, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	PicoBlade-to-PicoBlade
Overmolded	No
Overview	<u>PicoBlade Connector System</u>
Product Name	PicoBlade
Type	Discrete Wire Assembly
UPC	195842249967


**Physical**

Cable Length	300.00mm
Circuits (Loaded)	9
Color - Resin	Natural
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	4.629/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.25mm
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.50-1.00mm
Wire Size AWG	28
Wire/Cable Type	UL 1061

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing 2181100900-000

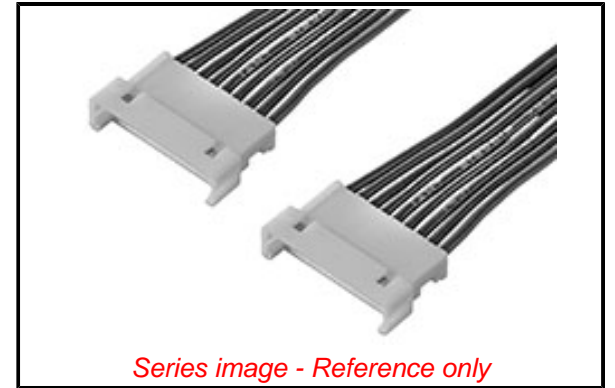

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

218110 Series

**Mates With**

PicoBlade Receptacle Housing 51021

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[218110-0903](#)