

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2181110200](#)  
**Status:** **Active**  
**Overview:** [PicoBlade Connector System](#)  
**Description:** PicoBlade Male-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Single Row, 75.00mm Length, 2 Circuits, Natural

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

|                        |  |
|------------------------|--|
| Product Family         | Cable Assemblies                           |
| Series                 | <a href="#">218111</a>                     |
| Application            | Signal, Wire-to-Wire                       |
| Assembly Configuration | Single Ended Connector                     |
| Connector to Connector | PicoBlade-to-Pigtail                       |
| Overmolded             | No   |
| Overview               | <a href="#">PicoBlade Connector System</a> |
| Product Name           | PicoBlade                                  |
| Type                   | Discrete Wire Assembly                     |
| UPC                    | 195842250031                               |


**Physical**

|                                |                      |
|--------------------------------|----------------------|
| Cable Length                   | 75.00mm              |
| Circuits (Loaded)              | 2                    |
| Color - Resin                  | Natural              |
| Gender                         | Male-Pigtail         |
| Lock to Mating Part            | Yes                  |
| Material - Metal               | Phosphor Bronze      |
| Material - Plating Mating      | Tin                  |
| Material - Plating Termination | Tin                  |
| Material - Resin               | Polyester            |
| Net Weight                     | 0.364/g              |
| Number of Rows                 | 1                    |
| Packaging Type                 | Bag                  |
| Pitch - Mating Interface       | 1.25mm               |
| Plating min - Mating           | 0.889µm              |
| Plating min - Termination      | 0.914µm              |
| Single Ended                   | Yes                  |
| Termination Interface: Style   | Crimp or Compression |
| Wire Insulation Diameter       | 0.50-1.00mm          |
| Wire Size AWG                  | 28                   |
| Wire/Cable Type                | UL 1061              |

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing 2181110200-000

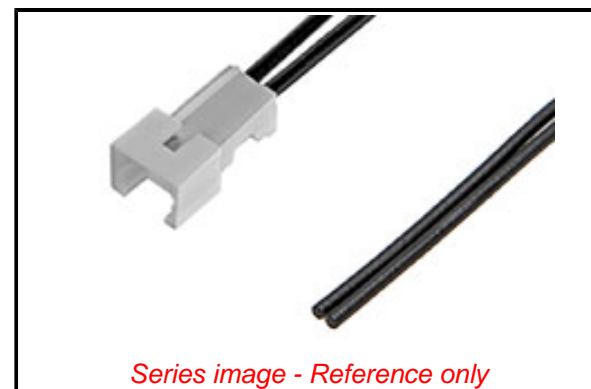

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[218111 Series](#)

**Mates With**

[PicoBlade Receptacle Housing 51021](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[218111-0200](#)