

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2183221021](#)  
**Status:** **Active**  
**Overview:** [DuraClik Connector System](#)  
**Description:** DuraClik ISL-to-DuraClik ISL Off-the-Shelf (OTS) Cable Assembly, 2.00mm Pitch, Single Row, 150.00mm Length, 2 Circuits, White

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">218322</a>
Application	Automotive, Signal, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	DuraClik ISL-to-DuraClik ISL
Overmolded	No
Overview	<a href="#">DuraClik Connector System</a>
Product Name	DuraClik
Type	Discrete Wire Assembly
UPC	195842351332

**Physical**

Cable Length	150.00mm
Circuits (Loaded)	2
Color - Resin	White
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	PBT
Net Weight	2.140/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	2.00mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.30mm
Wire Size AWG	22
Wire/Cable Type	1x0.35mm <sup>2</sup> FLRY-A


**Electrical**

Current - Maximum per Contact	3.0A
Voltage - Maximum	60V AC/DC

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	2183221021-000
---------------	----------------

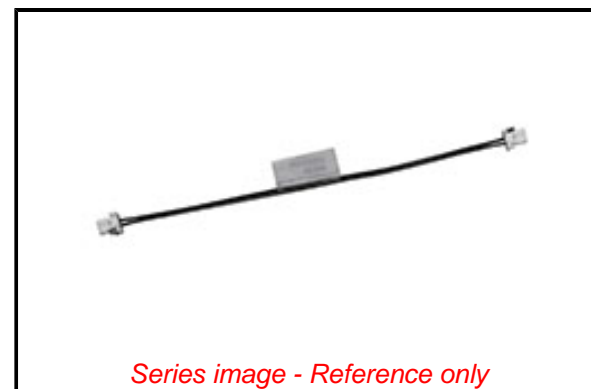

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[218322](#) Series

**Mates With**

DuraClik Right-Angle Header [502352](#) .  
DuraClik Vertical Header [560020](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[218322-1021](#)